

Clutch release bearing unit

Designed for smooth and long operations



Product Features



Tested for more than 1 million cycles for smooth and continuous operations



OE design for durability



Sealed with high performance grease



High grade alloy steel balls for heavy duty usage




Low noise levels



Compact and low weight design

Product Brief

- A clutch release bearing unit is used to engage and disengage the clutch via the diaphragm spring and pressure plate.
- Included in this compact design are provisions to guide the fork or piston radially.
- Our compact design combines a precision sheet metal bearing unit and polymer/steel sleeve or carrier, for manual gearbox applications against a dry clutch.
- We offer multiple designs with inner or outer ring rotation for a variety of applications.

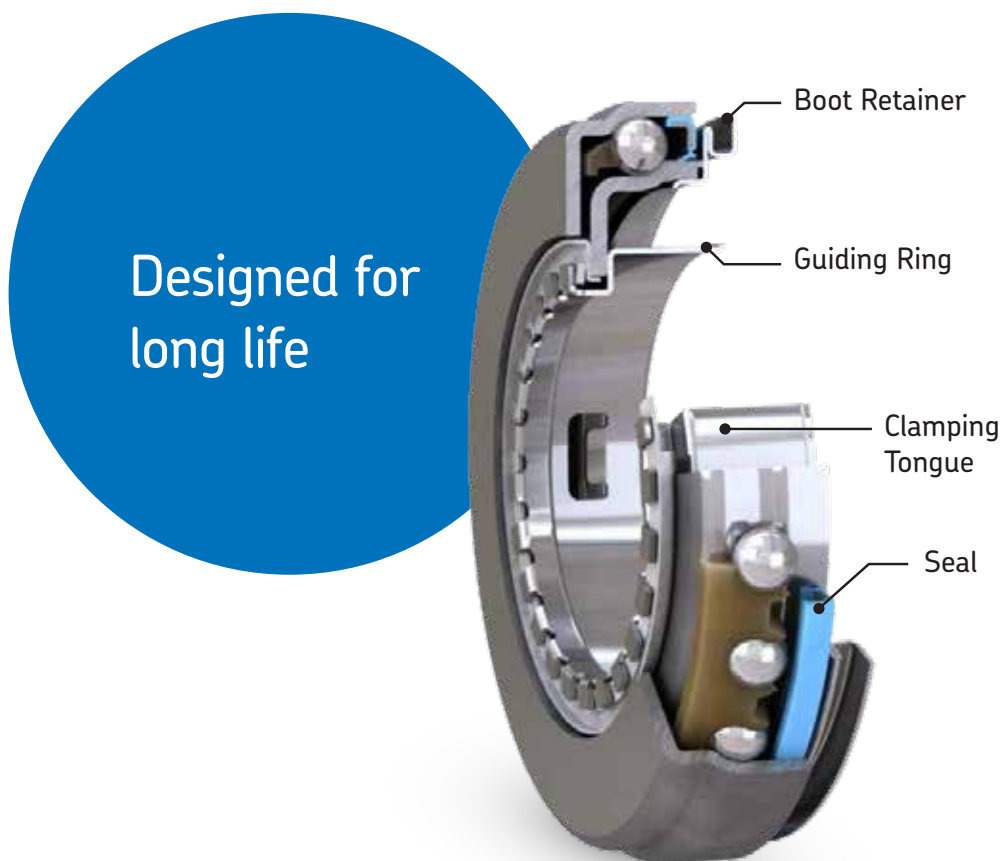

Higher number of operations with stop / start systems



Automated manual transmission or dual clutch transmission



Increased operating temperature



Increased higher application loads





Install confidence
Install SKF



S.No.	SKF Part No.	Make	Model	MRP	Case Qty	Coupon
1	VKC 3760	Maruti	Swift/ Dzire/ Ritz/ Brezza/ Ciaz/ SX4 (All Diesel)	3375	10	30
2	VKC 3761	Maruti	Ertiga/Baleno/Brezza/Celerio/ XL6	3947	10	20
3	VKC 3762	Maruti	WagonR/Alto/Alto800/Swift (All Petrol) /Ace	512	10	20
4	VKC 3795	Maruti	800	578	15	20
5	VKC 3767	Mahindra	Bolero/Scorpio (Old Model)	998	10	20
6	VKC 3768	Mahindra	Bolero/Scorpio (New Model)	1082	10	20
7	VKC 3769	Mahindra	TUV 300/ KUV 100/ Quanto	4199	10	35
8	VKC 3770	Mahindra	XYLO/GENIO (2.5L)	1025	10	15
9	VKC 3772	Mahindra	MAXXIMO/SUPRO TRUCK/JEETO (All Diesel)	611	10	10
10	VKC 3791	Mahindra	Armada/Jeep, Marshal, Pickup/Commander Pickup MSL	534	14	15
11	VKC 3774	TATA	AceSuper/Indica/Indigo/ZEST/BOLT	545	10	20
12	VKC 3778	TATA	NANO/IRIS	689	10	10
13	VKC 3781	Toyota	Etios (Petrol)	1087	10	10
14	VKC 3797	Hundai	i10 / i10 GRAND / i20/ SANTRO/ XCENT - Petrol	680	10	10
15	VKC 3798	Ford	Fiesta	3731	10	20
16	VKC 3784	Hyundai	i10 Grand(D)/Getz Prime/ Xcent/ Creta 1st Gen/ Verna(D)/ i20 (D)	793	10	10
17	VKC 3788	Honda	CITY/BRIO/CIVIC/JAZZ - F/L	1149	10	10
18	VKC 3790	Renault	DUSTER/SCALA/LODGY/LOGAN/PULSE	3962	10	20
19	VKC 3792	Mahidnra	MAXX PICKUP/ BOLERO CAMPER (4WD)/ BOLERO MAXI TRUCK	1253	10	10
20	VKC 3793	General Motors	Tavera	1262	10	10
21	VKC 3794	Ashok Leyland	DOST	731	10	10

Clutch release bearings from SKF are based on the design of an angular contact ball bearing.

These bearings are made of stamped steel inner and outer rings with precision ground raceways, a polymer cage and either seals or shields and are pregreased at the factory with a high quality lubricant

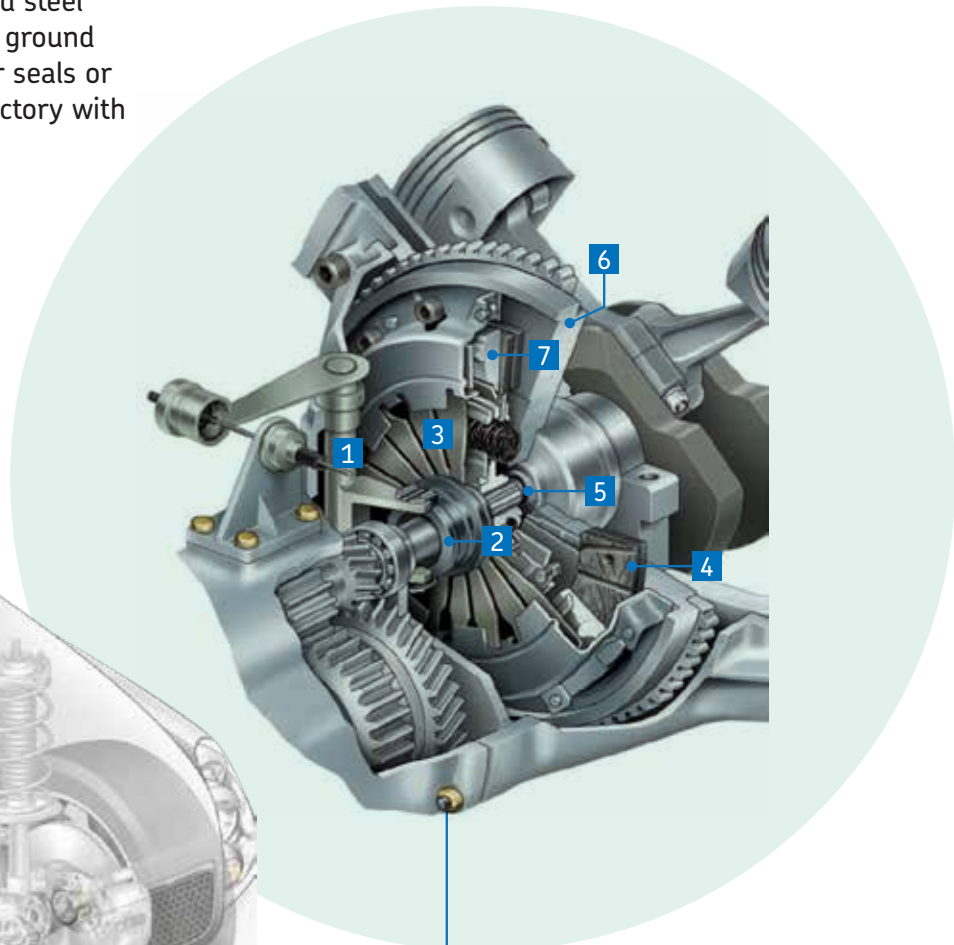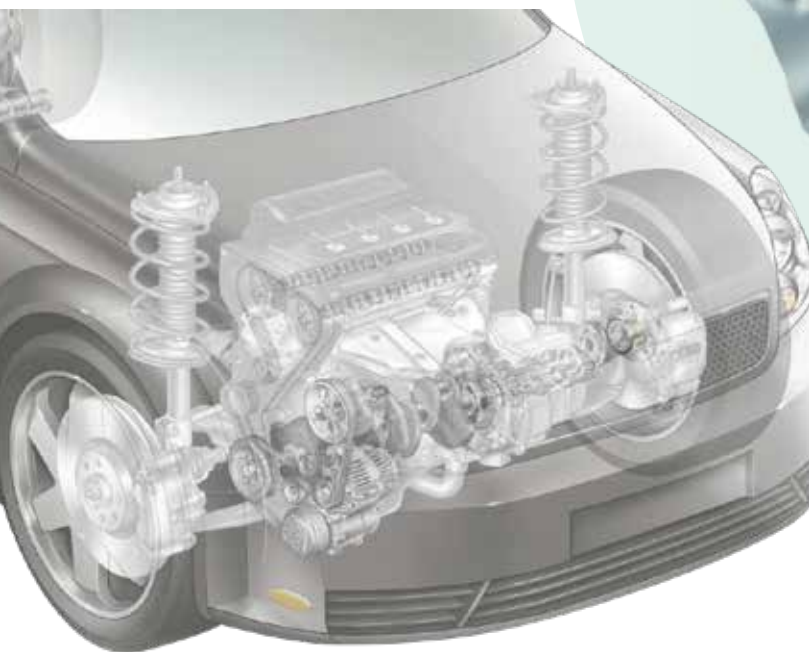

- 1 Fork/actuation device
- 2 Clutch release bearing
- 3 Diaphragm
- 4 Friction disc
- 5 Input shaft
- 6 Flywheel
- 7 Pressure plate

SKF India Limited
 Chinchwad, Pune-411 033
 Tel: +91-20-6611 2500, Fax +91-20-6611 2440
 Helpline: 1800 222 007 (Toll free from MTNL/BSNL landlines)
 or +91-22-6633 7777 (Normal STD charges apply)
 Website: www.skfindia.com
 CIN: L29130MH1961PLC011980

© SKF and Lincoln is a registered trademark of the SKF Group.

© SKF Group 2022

The contents of this publication are the copyright of the publisher and may not be reproduced (even extracts) unless prior written permission is granted. Every care has been taken to ensure the accuracy of the information contained in this publication but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

PUB 80/P5 19007 EN.IN · October 2022

Certain image(s) used under license from Shutterstock.com.

Version 1